


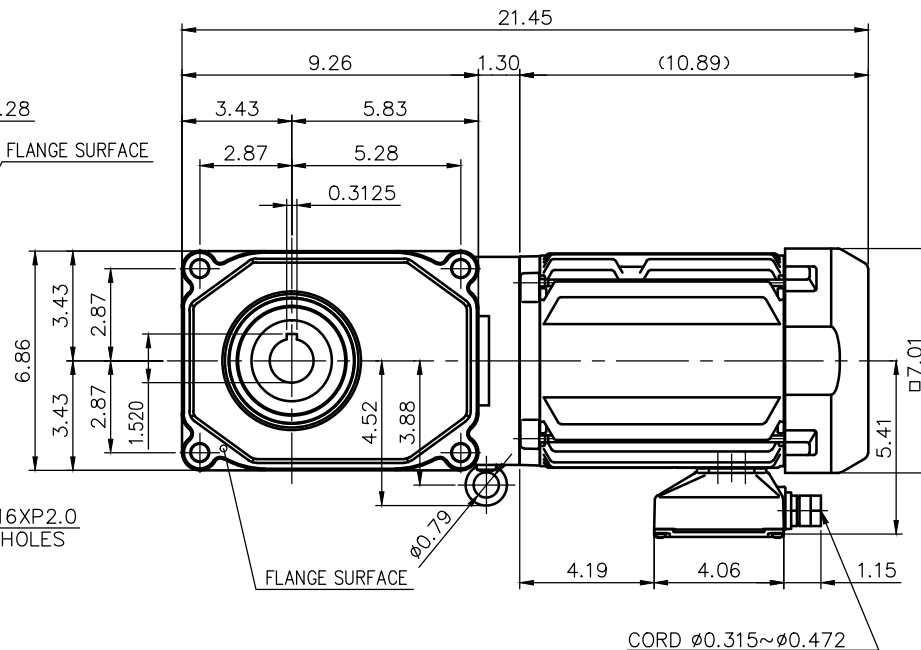

TYPE	3-PHASE INDUCTION MOTOR
FORM	TOTALLY ENCLOSED FAN COOLED P8
OUT PUT	2 HP
VOLTAGE	208/230/460/400 V
FREQ.	60/60/60/50 Hz
POLES	4
ROTATIONAL FREQUENCY	1800/1800/1800/1500 rpm
EFFICIENCY CLASS	IE3 EN60034-30 Standard
RATING	S1 CONT.
INS.CLASS	F

TYPE	GTR
FORM	45
RATIO	1/5 1/7.5 1/10 1/12.5 1/15 1/20 1/25 1/30 1/40 1/50 1/60
LUBRICATION	GREASE

TITLE					F3S45N~60—MV8AWN	
					DIMENSION OF MODEL	
DRAWING NO.			F3S45N—MV8AWN			
USER						
NOTICE						
APPROVE	Y.Ikeda	SCALE 1/6		UNIT in	DATE 2016.04.01	
CHECK	M.Iijima					
DESIGN	Y.Miura					
			NISSEI CORPORATION			