 





BRAKE SPECIFICATION

TYPE	BS3-22-180
BRAKE TYPE	SPRING CLOSE
INPUT VOLTAGE	DC 207V
POWER CONSUMPTION	49 W (at 75°C)
BRAKE TORQUE	152.7 in-lbs



MOTOR SPECIFICATION

TYPE	3-PHASE INDUCTION MOTOR
FORM	TOTALLY ENCLOSED FAN COOLED P9
OUT PUT	3 HP
VOLTAGE	208/230/460/400 V
FREQ.	60/60/60/50 Hz
POLES	4
ROTATIONAL FREQUENCY	1800/1800/1800/1500 rpm
EFFICIENCY CLASS	IE3 EN60034-30 Standard
RATING	S1 CONT.
INS.CLASS	F

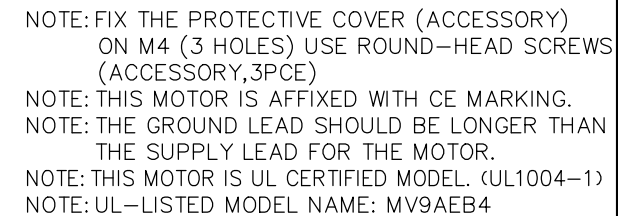

REDUCER SPECIFICATION

TYPE	GTR
FORM	50
RATIO	1/40 1/50 1/60
LUBRICATION	GREASE

TITLE					F3S50N40~60—MV9AEB4	
					DIMENSION OF MODEL	
DRAWING NO.			F3S50N—MV9AEB4			
USER						
NOTICE						
APPROVE	Y. Ikeda	SCALE 1/7		UNIT in	DATE 2015.05.01	
CHECK	M. Iijima					
DESIGN	Y. Miura					
			NISSEI CORPORATION			